


# Mounting plate VABA-B14-FL12-FL14

Part number: 8098889

FESTO

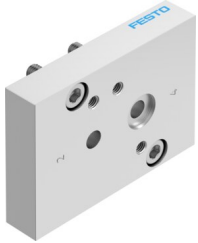

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	Any
Operating pressure	1.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 60 °C
Temperature of medium	-20 °C ... 60 °C
Ambient temperature	-20 °C ... 60 °C
Product weight	188 g
Type of mounting	With through-hole
Pneumatic connection 2	Flange 1/4 with NAMUR port pattern Flange 1/2 with NAMUR port pattern
Pneumatic connection 4	Flange 1/4 with NAMUR port pattern Flange 1/2 with NAMUR port pattern
Note on materials	RoHS-compliant
Material of sub-base	Wrought aluminum alloy