


# Exhaust plate VABF-B14-M3-G14

Part number: 8099350

FESTO

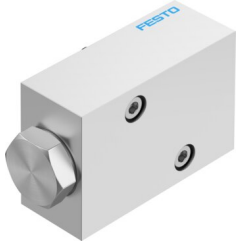

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	Any
Operating pressure	1.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 80 °C
Temperature of medium	-20 °C ... 80 °C
Ambient temperature	-20 °C ... 80 °C
Product weight	280.5 g
Type of mounting	With through-hole
Pneumatic connection 1	G1/4
Pneumatic connection 2	Flange 1/4 with NAMUR port pattern
Pneumatic connection 4	Flange 1/4 with NAMUR port pattern G1/4
Note on materials	RoHS-compliant
Controller housing material	Wrought aluminum alloy