


Exhaust plate VABF-B14-M3-N14

Part number: 8099627

FESTO

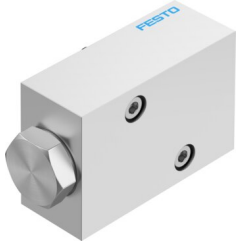

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	Any
Operating pressure	1.5 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-20 °C ... 80 °C
Temperature of medium	-20 °C ... 80 °C
Ambient temperature	-20 °C ... 80 °C
Product weight	280.5 g
Type of mounting	With through-hole
Pneumatic connection 1	1/4 NPT
Pneumatic connection 2	Flange 1/4 with NAMUR port pattern
Pneumatic connection 4	Flange 1/4 with NAMUR port pattern 1/4 NPT
Note on materials	RoHS compliant
Controller housing material	Wrought aluminum alloy