


# Axial kit EAMM-A-D32-40R

Part number: 8105826

FESTO

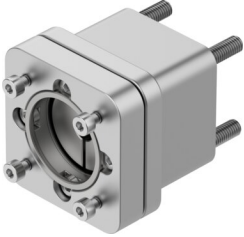

 [General operating condition](#)

## Data sheet

| Feature                  | Value            |
|--------------------------|------------------|
| Mounting position        | Any              |
| LABS (PWIS) conformity   | VDMA24364-B2-L   |
| Storage temperature      | -25 °C ... 60 °C |
| Relative air humidity    | 0 - 95%          |
| Degree of protection     | IP40             |
| Ambient temperature      | -10 °C ... 60 °C |
| Transferable torque      | 6.5 Nm           |
| Product weight           | 309 g            |
| Interface code, actuator | D32              |
| Interface code, motor in | 40R              |
| Note on materials        | RoHS compliant   |