


# Axial kit EAMM-A-P5-28B-38AA

Part number: 8107710

FESTO

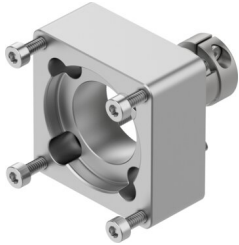

 [General operating condition](#)

## Data sheet

| Feature                          | Value                  |
|----------------------------------|------------------------|
| Nominal length                   | 17.5 mm                |
| Mounting position                | Any                    |
| Max. rotational speed            | 10000 rpm              |
| LABS (PWIS) conformity           | VDMA24364-B2-L         |
| Storage temperature              | -25 °C ... 60 °C       |
| Relative air humidity            | 0 - 95%                |
| Degree of protection             | IP40                   |
| Ambient temperature              | -10 °C ... 60 °C       |
| Mass moment of inertia           | 0.28 kgmm <sup>2</sup> |
| Transferable torque              | 1.1 Nm                 |
| Product weight                   | 59 g                   |
| Interface code, actuator         | P5-28B                 |
| Interface code, motor in         | 38AA                   |
| Interface code, coupling housing | 28B                    |
| Note on materials                | RoHS compliant         |