


Parallel kit EAMM-U-86-D60-80PB-102

Part number: 8107722

FESTO

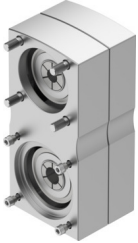

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|-----------------------|
| Size | 86 |
| Mounting position | Any |
| Gear ratio | 1:1 |
| Max. rotational speed | 5000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 175 kgmm ² |
| No-load driving torque | 0.25 Nm |
| Transferable torque | 9.5 Nm |
| Product weight | 2500 g |
| Interface code, actuator | D60 |
| Interface code, motor in | 80PB 80R |
| Note on materials | RoHS-compliant |