


# Axial kit EAMM-A-S62-70GA

Part number: 8110082

FESTO

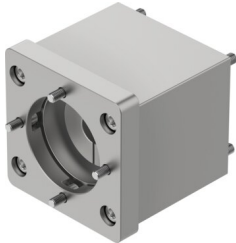

 [General operating condition](#)

## Data sheet

| Feature                  | Value            |
|--------------------------|------------------|
| Mounting position        | Any              |
| LABS (PWIS) conformity   | VDMA24364-B2-L   |
| Storage temperature      | -25 °C ... 60 °C |
| Relative air humidity    | 0 - 95%          |
| Degree of protection     | IP40             |
| Ambient temperature      | -10 °C ... 60 °C |
| Transferable torque      | 17 Nm            |
| Product weight           | 1109 g           |
| Interface code, actuator | S62              |
| Interface code, motor in | 70GA             |
| Note on materials        | RoHS compliant   |