


Vertical pressure supply plate VMPA14-VSP-QS3/8

FESTO

Part number: 8110623

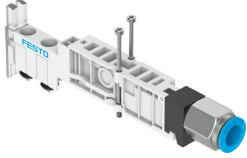

 General operating condition

Data sheet

| Feature | Value |
|----------------------------------|---|
| Width dimension | 14 mm |
| Symbol | 00991883 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Pilot pressure MPa | 0.3 MPa ... 0.8 MPa |
| Pilot pressure | 3 bar ... 8 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -5 °C ... 50 °C |
| Product weight | 55 g |
| Pneumatic connection 1 | QS-3/8 |
| Note on materials | RoHS-compliant |
| Supply plate material | PA-reinforced |