


Vertical pressure supply plate VMPA14-VSP-QS3/8

Part number: 8110623

FESTO

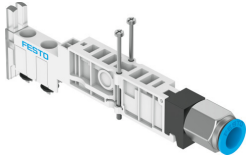

 General operating condition

Data sheet

Feature	Value
Width dimension	14 mm
Symbol	00991883
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	55 g
Pneumatic connection 1	QS-3/8
Note on materials	RoHS compliant
Supply plate material	PA-reinforced