


# Protective cap DHAS-DP-B23-25-L-N

Part number: 8116880

FESTO

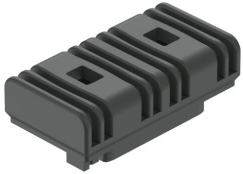

 [General operating condition](#)

## Data sheet

Feature	Value
Size	25
Stroke	22 mm
Design	for pneumatic gripper
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Suitable for battery production with reduced Cu/Zn/Ni values (F1a)
Ambient temperature	-10 °C ... 60 °C
Product weight	17.6 g
Type of mounting	Can be inserted in slot from above
Note on materials	RoHS-compliant
Protective cap material	NBR