


Axial kit EAMM-A-D40-50GA

Part number: 8117076

FESTO

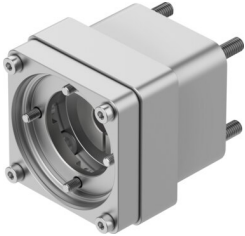

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	12.5 Nm
Product weight	411 g
Interface code, actuator	D40
Interface code, motor in	50GA
Note on materials	RoHS-compliant