


# Axial kit EAMM-A-D40-60RA

Part number: 8117078

FESTO

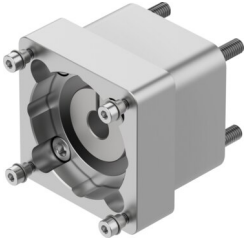

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	12.5 Nm
Product weight	336 g
Interface code, actuator	D40
Interface code, motor in	60RA
Note on materials	RoHS-compliant