


Manifold block-SET VABS-C12-6-S

Part number: 8122790

FESTO

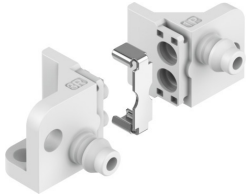

 [General operating condition](#)

Data sheet

Feature	Value
Width	13 mm
Mounting position	Any
Structural design	Lateral connection direction
Max. no. of valve positions	Versions according to customer specifications possible
Operating pressure	-0.1 MPa ... 0.7 MPa
Operating pressure	-1 bar ... 7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:1]
Information on operating and pilot media	Maximum particle size 5 µm
LABS (PWIS) conformity	VDMA24364 Zone III
Ambient temperature	5 °C ... 50 °C
Product weight	3 g
Type of mounting	With through-hole
Pneumatic connection 2	for 4 mm tubing I.D.
Note on materials	RoHS compliant
Manifold rail material	PBT