


Sub-base VABS-K2-10B-16-U14-P

Part number: 8122826

FESTO

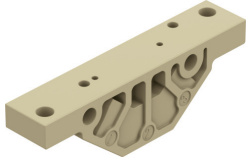

 [General operating condition](#)

Data sheet

Feature	Value
Size	10
Nominal width	1.6 mm
Fluid connector	Internal thread 1/4-28 UNF-2B
Mounting position	Any
Structural design	Connection direction downwards
Max. no. of valve positions	1
Flow direction	Non-reversible
Operating medium	Liquid media Gaseous media
Information on operating and pilot media	Observe resistance of materials that come into contact with media
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 70 °C
Temperature of medium	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Max. tightening torque for valve mounting	0.2 Nm
Product weight	7 g
Sub-base mounting type	With through-hole
Pneumatic valve mounting type	With internal thread
Note on materials	RoHS-compliant
Material of sub-base	PEEK