


# Connecting cable NEBV-HPG2-PN-0.3-N-LE2

Part number: 8122832

FESTO

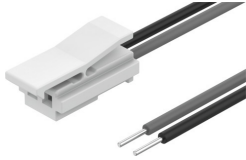

 General operating condition

## Data sheet

Feature	Value
Max. no. of solenoid coils	1
Cable designation	Without label holder
Mounting position	Any
Product weight	2 g
Electrical connection 1, function	Field device end Switching output
Electrical connection 1, design	Rectangular
Electrical connection 1, connection type	Cable with socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connection technology	Port pattern HP
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Push-pull with interlock to prevent unintentional pulling
Electrical connection 2, function	Power supply Control side
Electrical connection 2, connection type	2x single wires
Electrical connection 2, connection technology	Open end
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
DC operating voltage range	0 V ... 24 V
Shield	no
Information on operation	Only operate with external power reduction
Cable length	0.3 m
Cable characteristic	for static applications
Bending radius, fixed cable installation	≥11 mm
Cable diameter	0.96 mm
Degree of protection	IP40
Ambient temperature	0 °C ... 50 °C
Storage temperature	-20 °C ... 70 °C
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	0 - No corrosion stress
Housing material	PEEK
Housing colour	Gray
Insulating sheath material	PVC