


Pneumatic valve VOFC-LT-M32C-MC-N14-FN

Part number: 8122933

FESTO

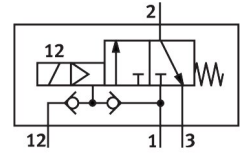

[PDF](#) General operating condition

Data sheet

Feature	Value
Normal nominal flow rate (normalized to DIN 1343)	703 l/min
Operating pressure	0.1 MPa ... 0.8 MPa
Operating pressure	1 bar ... 8 bar
Operating pressure	14.5 psi ... 116 psi
Degree of protection	IP65
Certificate issuing authority	TÜV 968/V 1251.00/24
Symbol	00992275
Safety function	Safe venting
Safety integrity level (SIL)	Up to SIL 3 high demand mode Up to SIL 3 low demand mode
Information on operating pressure	0 – 0.8 bar with external pilot air
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant