


# Axial kit EAMM-A-D32-40RA

Part number: 8125610

FESTO

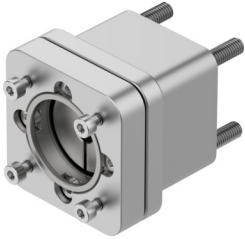

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	6.5 Nm
Product weight	309 g
Interface code, actuator	D32
Interface code, motor in	40RA
Note on materials	RoHS-compliant