


# Control plate DADG-FM-VDE1G14

Part number: 8131548

FESTO

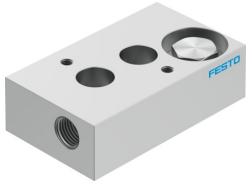

 [General operating condition](#)

## Data sheet

Feature	Value
Based on norm	VDI/VDE 3845 (NAMUR)
Mounting position	Any
Operating pressure	0.2 MPa ... 0.8 MPa
Operating pressure	2 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-20 °C ... 80 °C
Max. tightening torque	23 Nm
Product weight	274.5 g
Type of mounting	Threaded direct mounting on end cap
Pneumatic connection	G1/4
Note on materials	RoHS-compliant
Seals material	NBR High-alloy stainless steel
Housing material	Aluminum, anodized
Material of screws	Brass, nickel-plated