


# Manifold block VABS-S7-RB-B-G14-VDE2-R12

Part number: 8141067

FESTO

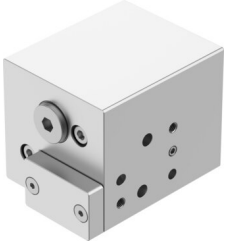

 [General operating condition](#)

## Data sheet

Feature	Value
Mounting position	Any
Pilot air supply port	External Internal
Operating pressure	0 MPa ... 1 MPa
Operating pressure	0 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65 In mounted state
Product weight	750 g
Type of mounting	With through-hole
Pilot air port 12	G1/4
Pneumatic connection 1	G1/4
Pneumatic connection 2	VDI/VDE 3847 (NAMUR)
Pneumatic connection 3	G1/4
Note on materials	RoHS-compliant
Material of sub-base	Aluminum, ematal coated
Seals material	NBR