


Double nipple NPFC-DS-M5-G18-M

Part number: 8142591

FESTO

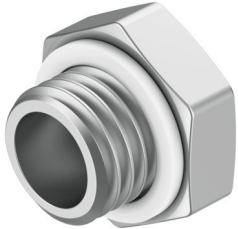

 [General operating condition](#)

Data sheet

Feature	Value
Threaded fitting material	Brass, nickel-plated
Pack size	10
Operating pressure	-0.95 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-10 °C ... 60 °C
Nominal tightening torque, pneumatic connection 1	10.55 Nm
Nominal tightening torque, pneumatic connection 2	1.78 Nm
Tolerance for nominal tightening torque	±20%
Product weight	8.96 g
Pneumatic connection 1	G1/8
Pneumatic connection 2	M5
Note on materials	RoHS compliant
Seals material	PVC