


Gripper jaw mounting EHAA-G1-B18-16-GGA1

Part number: 8146633

FESTO

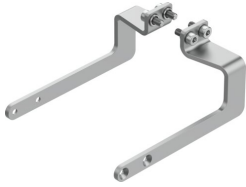

 [General operating condition](#)

Data sheet

Feature	Value
Size	16
Mounting position	Any
Structural design	horizontal gripper mounting
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-20 °C ... 70 °C
Relative air humidity	0 - 100 %
Ambient temperature	0 °C ... 40 °C
Product weight	100 g
Note on materials	RoHS-compliant
Material of screws	High-alloy steel High-alloy stainless steel
Bracket material	High-alloy stainless steel
Material of centering elements	High-alloy steel