


Gripper jaw mounting EHAA-G1-B18-16-GGA1-AP

Part number: 8146634

FESTO

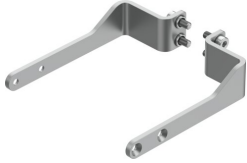

 [General operating condition](#)

Data sheet

| Feature | Value |
|----------------------------------|--|
| Size | 16 |
| Mounting position | Any |
| Structural design | vertical gripper mounting |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -20 °C ... 70 °C |
| Relative air humidity | 0 - 100 % |
| Ambient temperature | 0 °C ... 40 °C |
| Product weight | 95 g |
| Note on materials | RoHS-compliant |
| Material of screws | High-alloy steel High-alloy stainless steel |
| Bracket material | High-alloy stainless steel |
| Material of centering elements | High-alloy steel |