


Power supply unit CACN-11A-7-20-G2

Part number: 8149585

FESTO

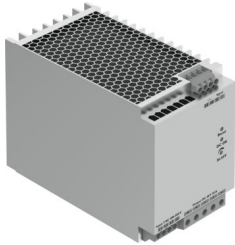

 [General operating condition](#)

Data sheet

Feature	Value
Width	96 mm
Height	130 mm
Length	179 mm
Mounting position	Open convection
Primary supply	Three-phase
Input current	1.7 - 2.1 A
Nominal output voltage DC	48 V
Nominal output current	20 A
Input voltage range AC	400 V ... 500 V
Power failure buffering	25 ms
Mains frequency	45 Hz ... 65 Hz
Certification	c UL us - Listed (OL)
CE marking (see declaration of conformity)	As per EU EMC directive As per EU low voltage directive
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-40 °C ... 85 °C
Relative air humidity	95%
Degree of protection	IP20
Ambient temperature	-25 °C ... 70 °C
Product weight	2500 g
Type of mounting	With DIN rail
Note on materials	RoHS compliant