


# Plastic tubing PUN-H-F-8X1,25-TBL

Part number: 8153396

FESTO

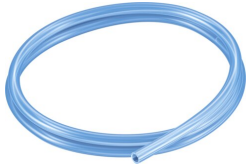

 General operating condition

## Data sheet

Feature	Value
Outside diameter	8 mm
Bending radius relevant for flow rate	37 mm
Inside diameter	5.7 mm
Min. bending radius	21 mm
Application note	Tubing without printing TPE-U, ether-based
Symbol	00997424
Tubing characteristics	Suitable for energy chains
Operating pressure for entire temperature range	-0.095 MPa ... 0.6 MPa
Operating pressure for entire temperature range	-0.95 bar ... 6 bar
Operating pressure for entire temperature range	-13.775 psi ... 87 psi
Temperature-dependent operating pressure	-0.095 MPa ... 1 MPa
Temperature-dependent operating pressure	-0.95 bar ... 10 bar
Temperature-dependent operating pressure	-13.775 psi ... 145 psi
Information on operating pressure	Water: temperature-dependent operating pressure, see diagram, max. 0.3 MPa at 0 - 60 °C
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:] Water (liquid, ice-free)
Material fire test	UL94 HB
LABS (PWIS) conformity	VDMA24364-B2-L
Cleanroom suitability, measured according to ISO 14644-14	Statically installed element, no meaningful evaluation possible according to ISO 14644-1
For use in the food industry	See declaration of conformity
Ambient temperature	-35 °C ... 60 °C
Product weight by length	0.0285 kg/m
Pneumatic connection	For plug connection outside diameter 8 mm For barbed fitting, inside diameter 6 mm, with union nut
Color	translucent blue
Shore hardness	D 52 +/-3
Note on materials	RoHS compliant
Material of pneumatic tubing	TPE-U(PU)