


# Axial kit EAMM-A-D100-150A-S1

Part number: 8157276

FESTO

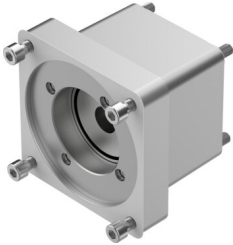

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	103 mm
Mounting position	Any
Max. rotational speed	4500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	280 kgmm <sup>2</sup>
Transferable torque	143 Nm
Product weight	3444 g
Interface code, actuator	D100
Interface code, motor in	140A 150A
Note on materials	RoHS-compliant