


# Axial kit EAMM-A-L95-150A-G2

Part number: 8157280

FESTO

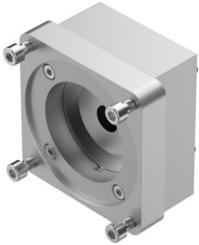

 [General operating condition](#)

## Data sheet

| Feature                  | Value                 |
|--------------------------|-----------------------|
| Nominal length           | 76 mm                 |
| Mounting position        | Any                   |
| Max. rotational speed    | 4500 rpm              |
| LABS (PWIS) conformity   | VDMA24364-B2-L        |
| Storage temperature      | -25 °C ... 60 °C      |
| Relative air humidity    | 0 - 95 %              |
| Degree of protection     | IP40                  |
| Ambient temperature      | -10 °C ... 60 °C      |
| Mass moment of inertia   | 374 kgmm <sup>2</sup> |
| Transferable torque      | 143 Nm                |
| Product weight           | 3180 g                |
| Interface code, actuator | L95                   |
| Interface code, motor in | 140A<br>150A          |
| Note on materials        | RoHS-compliant        |