


# Sub-base VMPA14-AP-4-EMG-D2-8-S

Part number: 8157742

FESTO

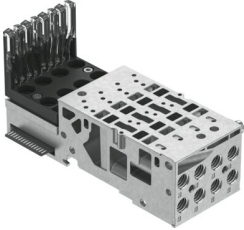

 [General operating condition](#)

## Data sheet

Feature	Value
Width	65.5 mm
Length	107.3 mm
Width dimension	14 mm
Max. no. of valve positions	4
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 Zone III
Storage temperature	-20 °C ... 60 °C
Ambient temperature	-5 °C ... 50 °C
Product weight	320 g
Pneumatic connection 2	G1/8
Pneumatic connection 4	G1/8
Note on materials	RoHS compliant
Material of sub-base	Die-cast aluminum