


# Sub-base VMPA14-AP-4-EMM-8-SK

Part number: 8157745

FESTO

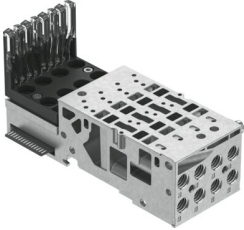

 [General operating condition](#)

## Data sheet

| Feature                          | Value                   |
|----------------------------------|-------------------------|
| Width                            | 65.5 mm                 |
| Length                           | 107.3 mm                |
| Width dimension                  | 14 mm                   |
| Max. no. of valve positions      | 4                       |
| Operating pressure               | -0.09 MPa ... 1 MPa     |
| Operating pressure               | -0.9 bar ... 10 bar     |
| Pilot pressure MPa               | 0.3 MPa ... 0.8 MPa     |
| Pilot pressure                   | 3 bar ... 8 bar         |
| Corrosion resistance class (CRC) | 0 - No corrosion stress |
| LABS (PWIS) conformity           | VDMA24364 zone III      |
| Storage temperature              | -20 °C ... 60 °C        |
| Ambient temperature              | -5 °C ... 50 °C         |
| Product weight                   | 320 g                   |
| Pneumatic connection 2           | G1/8                    |
| Pneumatic connection 4           | G1/8                    |
| Note on materials                | RoHS-compliant          |
| Material of sub-base             | Die-cast aluminum       |