


# Sub-base VMPA-FB-AP-1-EMM-P5-SK

Part number: 8161059

FESTO

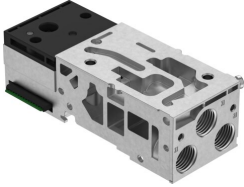

 [General operating condition](#)

## Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Width dimension	41 mm
Max. no. of valve positions	4
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 60 °C
Ambient temperature	-5 °C ... 50 °C
Product weight	175 g
Pneumatic connection 1	G1/4
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum