


# Pressure sequence valve VD-3-PK-3

Part number: 9270

FESTO

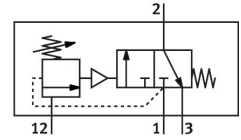

[PDF](#) General operating condition

## Data sheet

Feature	Value
Normal nominal flow rate (normalized to DIN 1343)	100 l/min
Pneumatic working port	PK-3
Operating pressure	0.18 MPa ... 0.8 MPa
Operating pressure	1.8 bar ... 8 bar
Nominal width	2.5 mm
Symbol	00991739
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	-10 °C ... 60 °C
Product weight	220 g
Type of mounting	With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Note on materials	RoHS-compliant