


# Bulkhead quick connector SCK-PK-6-KU

Part number: 9389

FESTO

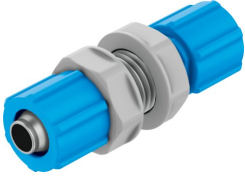

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal width	5.3 mm
Mounting position	Any
Design	Bulkhead
Pack size	10
Operating pressure for entire temperature range	-0.095 MPa ... 1 MPa
Operating pressure for entire temperature range	-0.95 bar ... 10 bar
Operating pressure for entire temperature range	-13.775 psi ... 145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Pneumatic connection 1	for pneumatic tubing outside diameter 8 mm For barbed fitting, inside diameter 6 mm, with union nut
Pneumatic connection 2	for pneumatic tubing outside diameter 8 mm for barbed fitting, inside diameter 6 mm, with nut
Material of union nut	POM
Note on materials	RoHS-compliant
Nut material	POM
Connector material	POM